




AF

Accouplement **rigide** A rainure de clavette

- Serrage par vis de pression
- Matière: acier 34C10
- Avec rainure de clavette

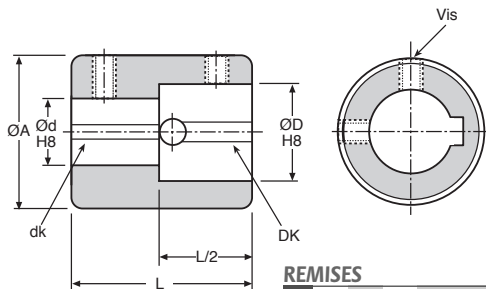

REMISES

Qté	1+	6+	20+	40+
Rem.	Prix	-15%	-20%	Sur demande


REFERENCE	ØD	Clavette		Clavette		ØA	L	Vis	Stock*	Prix Uni. 1 à 5
		DK	Ød	dK						
AF10	10	3	10	3	20	30	M4	✓	26,17 €	
AF12-10/12	12	4	10	3	28	36	M5	-	27,84 €	
AF12	12	4	12	4	28	36	M5	✓	27,84 €	
AF15-10/15	15	5	10	3	28	36	M5	-	27,84 €	
AF15-12/15	15	5	12	4	28	36	M5	-	27,84 €	
AF15	15	5	15	5	28	36	M5	✓	27,84 €	
AF20-15/20	20	6	15	5	32	40	M6	-	35,19 €	
AF20	20	6	20	6	32	40	M6	✓	35,19 €	
AF24	24	8	24	8	40	54	M6	-	40,90 €	
AF25-20/25	25	8	20	6	40	54	M8	-	40,90 €	
AF25	25	8	25	8	40	54	M8	✓	40,90 €	
AF30-25/30	30	8	25	8	50	54	M8	-	45,04 €	
AF30	30	8	30	8	50	54	M8	✓	45,04 €	

*Dans la limite du disponible

Accouplement rigide

A moyeu fendu

- Serrage par mâchoire
- Matière : acier 34C10

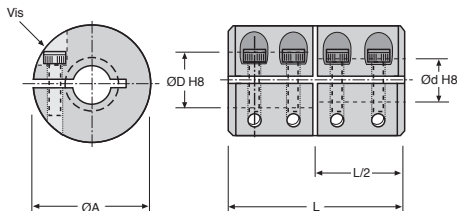

REMISES

Qté	1+	6+	20+	40+
Rem.	Prix	-15%	-20%	Sur demande

REFERENCE	ØD	Ød	ØD maxi.	ØA	Vis	L	Stock*	Prix Uni. 1 à 5
SC5	5	5	10,0	22	M3	30	✓	25,25 €
SC5-5/6	6	5	10,0	22	M3	30	-	25,25 €
SC6	6	6	10,0	22	M3	30	✓	25,25 €
SC8-6/8	8	6	10,0	22	M3	30	✓	25,25 €
SC8	8	8	10,0	22	M3	30	✓	25,25 €
SC10-10/8	10	8	13,0	30	M4	40	✓	40,90 €
SC10	10	10	13,0	30	M4	40	✓	40,90 €
SC12-10/10	10	10	19,5	36	M5	50	-	42,80 €
SC12-10/12	12	10	19,5	36	M5	50	✓	42,80 €
SC12	12	12	19,5	36	M5	50	✓	42,80 €
SC15-12/12	12	12	23,0	40	M5	50	-	51,03 €
SC15-12/15	15	12	23,0	40	M5	50	-	51,03 €
SC15	15	15	23,0	40	M5	50	✓	51,03 €
SC20-15/15	15	15	25,0	50	M6	65	-	56,49 €
SC20-15/20	20	15	25,0	50	M6	65	-	56,49 €
SC20	20	20	25,0	50	M6	65	✓	56,49 €
SC25-20/20	20	20	33,0	60	M8	65	-	104,51 €
SC25-20/25	25	20	33,0	60	M8	65	-	104,51 €
SC25	25	25	33,0	60	M8	65	✓	104,51 €
SC30-25/25	25	25	43,0	70	M8	80	-	117,21 €
SC30-25/30	30	25	43,0	70	M8	80	-	117,21 €
SC30	30	30	43,0	70	M8	80	✓	117,21 €

*Dans la limite du disponible